

GRUNDFOS WASTEWATER PUMPS INSTANT DELIVERY

Wastewater pumps available for instant delivery

- DP Drainage pumps
- EF Effluent pumps
- SEG Grinder pumps
- SE/SL 1 - 30 kW Sewage pumps



Revision November 2016

be
think
innovate

GRUNDFOS 

FAST REPLACEMENT FOR IMPROVED PERFORMANCE AND HIGH EFFICIENCY!

Welcome to the Grundfos fast replacement guide for wastewater pumps. With this guide, you will be able to easily select from among our drainage, effluent, grinder and smaller wastewater pumps available from stock to replace your existing wastewater pumps.

For faster replacement, Grundfos has created a stock of more than 1,200 sewage pumps at a central location to ensure fast delivery of your replacement pumps. To ease the selection of these pumps, this guide helps find your required pump.

We have also included the order number for the adapter needed to install the pumps on a Flygt auto-coupling.

THE REPLACEMENT GUIDE FEATURES:

- Lists Grundfos pumps on stock
- Performance curve for duty-point selection
- Searchable PDF file, for easily figuring out which item no. matches the pumps in stock

GRUNDFOS DP AND EF PUMPS

DP drainage pumps and EF effluent pumps are heavy duty, long lasting, professional pumps made for easy installation and service. The pumps are available with a standard motor and protection and as the Grundfos AutoAdapt version with build-in level sensors and a wide range of motor protection features.

GRUNDFOS SEG PUMPS

The SEG grinder pumps comprises sturdy and efficient wastewater pumps for public and private raw sewage systems. Thanks to the efficient and long lasting cutter system and high pump pressure are the SEG pumps the right choice for pumping sewage over long distances in small diameter (down 32 mm) pipes.

The range is also available with the revolutionising build-in level sensors and efficient motor protection.

GRUNDFOS SE & SL PUMPS

SE and SL pumps are designed to fit into almost any wastewater application with their slim design and standardised connection flanges. Available for both submersible and dry installation, they are recognised for their troublefree operation and low energy consumption. Grundfos SE and SL pumps are also designed for easy service and maintenance – ensuring low life cycle costs.

For more product information, please see Grundfos Product Center

[Grundfos product center](#)



HOW DOES THE GUIDE WORK?

Follow one of these two simple approaches to find the right pump for your installation:

The pocket guide is a supplement to our online [Grundfos Product Center](#), providing you with quick access to relevant Grundfos pump alternatives. The pump selection in this guide is based on pumps available at a central location for quick delivery.

If you know the Grundfos product number for the pump you want to order, you can search for the product number to see if this is in stock or if there is a related product number which is in stock. A related product number is a pump with the same performance criteria, but with a slightly different design. If you do not know the product number, you can size and select your pump requirements through five simple steps to order the pump that fits your needs.

For more replacement solutions, please visit Grundfos Product Center at [Grundfos product Center](#) or contact your local Grundfos sales office.

FIND YOUR REPLACEMENT PUMP VIA A PRODUCT NUMBER

- 1) Open the PDF document, Press "Ctrl"+F
- 2) Type in the product number. If the product number appears in
 - a. "Product number (In stock)" – your pump is in stock
 - b. "Related product numbers" – the pumps to the left are in stock and might be used
- 3) Contact your local Grundfos office for your next delivery


FIND YOUR REPLACEMENT PUMP USING PRODUCT CHARACTERISTICS

- 1) Identify if your pump is:
 - a. DP and EF drainage and effluent pumps (p. 6 - 7)
 - b. SEG Grinder pumps (p. 8 - 9)
 - c. SE/SL pumps with 50 and 65 mm free passage (p. 10 - 12)
 - d. SE/SL 1-11kW vortex pumps with 80 and 100 mm free passage (p. 14 - 17)
 - e. SE/SL 1-11kW S-tube pumps with 80 and 100 mm free passage (p. 18 - 20)
 - f. SE/SL 9-30kW vortex pumps with 80 mm free passage (p. 22 - 23)
 - g. SE/SL 9-30kW S-tube high pressure pumps (p. 24 - 25)
 - h. SE/SL 9-30kW S-tube high flow pumps (p. 26 - 27)
 - i. EF effluent pumps with Ex proof motor (p. 28)
 - j. SEG grinder pumps with Ex proof motor (p. 29)
 - k. SL vortex and S-tube pumps with Ex proof motor (p. 30 - 31)
- 2) Go to the pages indicated above
- 3) Identify the Q and H curve no.
- 4) Go to the table to select one of the pumps in stock via "Product number (In Stock)"
- 5) Contact your local Grundfos office for your next delivery

VIEW DETAILS AND COMPARE PERFORMANCE ONLINE

Once you have found your pump, visit the online Grundfos Product Center at [Grundfos Product Center](#) and type in the product number, for more information about the selected replacement pump.

DP 0.9 - 2.6 KW DRAINAGE PUMPS WITH 10 MM FREE PASSAGE (STANDARD MOTOR VERSION) A = STARTER BOX INCLUDED

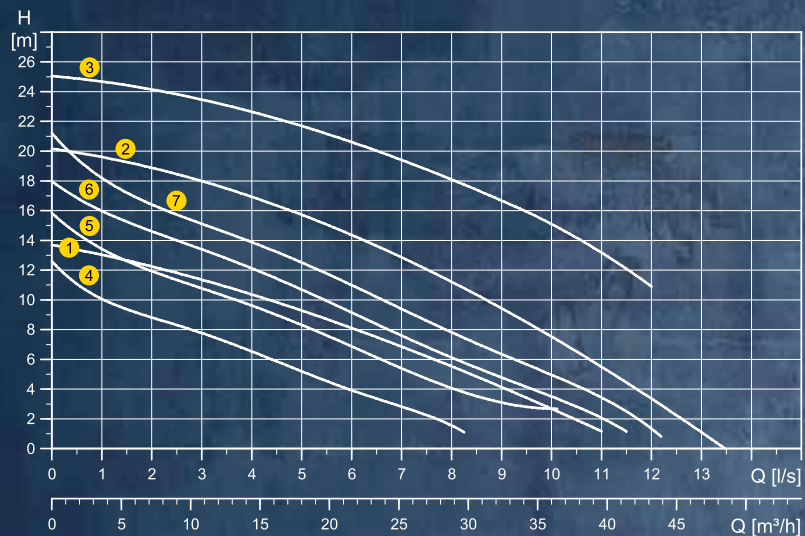


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	0,9	10	R 2	DP10.50.09.2.50B	96104204	96104204; 96104205*; 96104206; 96104207*	
2	1,5	10	R 2	DP10.50.15.2.50B	96104208	96104208; 96104209*; 96104210; 96104211*	
2	1,5	10	R 2	DP10.50.15.A.2.50B	96104210	96104208; 96104209*; 96104210; 96104211*	
3	2,6	10	DN 65	DP10.65.26.2.50B	96106542	96106542; 96106543*; 96106544; 96106545*	95918167 - DN65/65
3	2,6	10	DN 65	DP10.65.26.A.2.50B	96106544	96106542; 96106543*; 96106544; 96106545*	95918167 - DN65/65

EF 0.6 - 1.5 KW EFFLUENT PUMPS WITH 30 MM FREE PASSAGE (STANDARD MOTOR VERSION) E = AUTOADAPT VERSION

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
4	0,6	30	R 2	EF30.50.06.E.2.50B	96877510	96106550; 96106551*; 96106552; 96106553*; 96566084; 96566086; 96566087*; 96877510; 96877514	
4	0,6	30	R 2	EF30.50.06.2.50B	96106550	96106550; 96106551*; 96106552; 96106553*; 96566084; 96566086; 96566087*; 96877510; 96877514	
5	0,9	30	R 2	EF30.50.09.2.50B	96115115	96115115; 96115116*; 96115117; 96115118*; 96566088; 96566090*; 96877516; 96877532	
6	1,1	30	R 2	EF30.50.11.2.50B	96106558	96106558; 96106559*; 96106560; 96106561*; 96566091; 96566092; 96566093*; 96878445; 96878447	
7	1,5	30	R 2	EF30.50.15.2.50B	96104196	96104196; 96104197*; 96104198; 96104199*; 96566094; 96566095; 96566096*; 96878448; 96878449	




SEG 0.9 - 4.0 KW GRINDER PUMPS (STANDARD MOTOR VERSION) E = AUTOADAPT VERSION

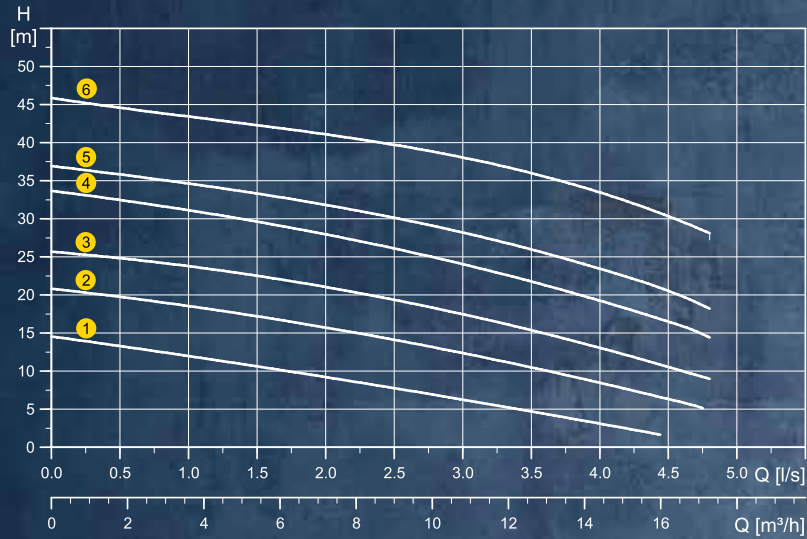

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	0,9		DN 40	SEG.40.09.E.2.1.502	96878505	96075893; 96075894; 96076161; 96076212; 96076213; 96076228; 96878505; 96878507	98247423 - DN40
1	0,9		DN 40	SEG.40.09.E.2.50B	96878506	96075897; 96075898; 96075919; 96076162; 96076214; 96076215; 96076229; 96878506; 96878508	98247423 - DN40
2	1,2		DN 40	SEG.40.12.E.2.1.502	96878509	96075901; 96075902; 96076163; 96076216; 96076217; 96076230; 96878509; 96878512	98247423 - DN40
2	1,2		DN 40	SEG.40.12.E.2.50B	96878510	96075905; 96075906; 96075920; 96076164; 96076218; 96076219; 96076231; 96878510; 96878513	98247423 - DN40
3	1,5		DN 40	SEG.40.15.E.2.1.502	98280726	98280724; 98280725; 98280726; 98280948	98247423 - DN40
3	1,5		DN 40	SEG.40.15.E.2.50B	96878514	96075909; 96075910; 96075921; 96076165; 96076220; 96076221; 96076232; 96878514; 96878515	98247423 - DN40

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
4	2,6		DN 40	SEG.40.26.E.2.50B	96878516	96075913; 96075914; 96075922; 96076166; 96076222; 96076223; 96076233; 96878516; 96878517	98247423 - DN40
5	3,1		DN 40	SEG.40.31.E.2.50B	96878518	96075915; 96075916; 96075923; 96076167; 96076224; 96076225; 96076234; 96878518; 96878519	98247423 - DN40
6	4,0		DN 40	SEG.40.40.E.2.50B	96878520	96075917; 96075918; 96075924; 96076168; 96076226; 96076227; 96076235; 96878520; 96878521	98247423 - DN40
1	0,9		DN 40	SEG.40.09.2.1.502	96075893	96075893; 96075894; 96076161; 96076212; 96076213; 96076228; 96878505; 96878507	98247423 - DN40
1	0,9		DN 40	SEG.40.09.2.50B	96075897	96075897; 96075898; 96075919; 96076162; 96076214; 96076215; 96076229; 96878506; 96878508	98247423 - DN40
2	1,2		DN 40	SEG.40.12.2.1.502	96075901	96075901; 96075902; 96076163; 96076216; 96076217; 96076230; 96878509; 96878512	98247423 - DN40
2	1,2		DN 40	SEG.40.12.2.50B	96075905	96075905; 96075906; 96075920; 96076164; 96076218; 96076219; 96076231; 96878510; 96878513	98247423 - DN40
3	1,5		DN 40	SEG.40.15.2.1.502	98280724	98280724; 98280725; 98280726; 98280948	98247423 - DN40
3	1,5		DN 40	SEG.40.15.2.50B	96075909	96075909; 96075910; 96075921; 96076165; 96076220; 96076221; 96076232; 96878514; 96878515	98247423 - DN40
4	2,6		DN 40	SEG.40.26.2.50B	96075913	96075913; 96075914; 96075922; 96076166; 96076222; 96076223; 96076233; 96878516; 96878517	98247423 - DN40
5	3,1		DN 40	SEG.40.31.2.50B	96075915	96075915; 96075916; 96075923; 96076167; 96076224; 96076225; 96076234; 96878518; 96878519	98247423 - DN40
6	4,0		DN 40	SEG.40.40.2.50B	96075917	96075917; 96075918; 96075924; 96076168; 96076226; 96076227; 96076235; 96878520; 96878521	98247423 - DN40

1 - 11 KW S-TUBE & VORTEX PUMPS WITH 50 AND 65 MM FREE PASSAGE (STANDARD MOTOR VERSION)

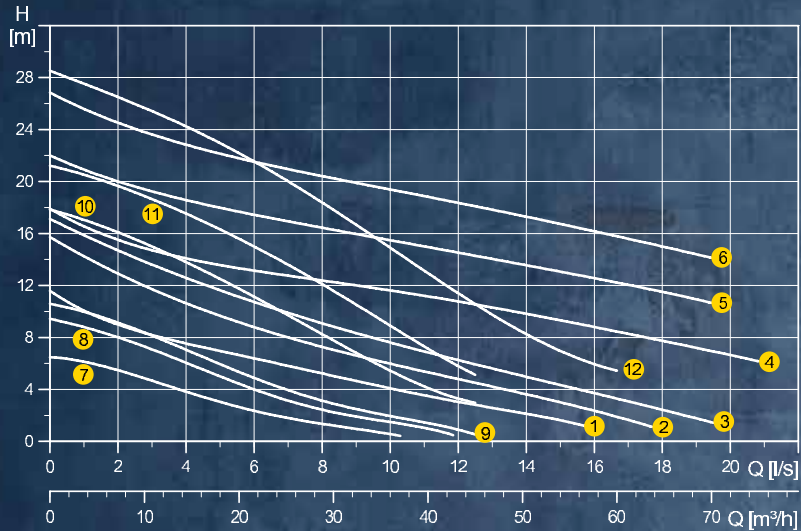


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	0,9	50	65	SL1.50.65.09.2.50B	96106566	96106566; 96106567; 96106568*; 96106569*; 96106570; 96106571; 96106572*; 96878451; 96878453*	95918167 - DN65/65
2	1,1	50	65	SL1.50.65.11.2.50B	96104129	96104129; 96104130; 96104131*; 96104132*; 96104133; 96104134; 96104135*; 96878455; 96878457*	95918167 - DN65/65
3	1,5	50	65	SL1.50.65.15.2.50B	96104118	96104118; 96104119; 96104120*; 96104121*; 96104122; 96104123; 96104124*; 96878458; 96878472*	95918167 - DN65/65
4	2.2	50	65	SL1.50.65.22.2.50D.C	98624257	98624257; 98626069; 98626078; 98626085; 98626297; 98626303; 98626308; 98626314; 98626476*; 98626482*; 98626487*; 98626553*; 98626692*; 98626698*; 98626703*; 98626759*	95918167 - DN65/65
5	3.0	50	65	SL1.50.65.30.2.50D.C	98624258	98624258; 98626070; 98626079; 98626086; 98626298; 98626304; 98626309; 98626315; 98626477*; 98626483*; 98626488*; 98626554*; 98626693*; 98626699*; 98626704*; 98626760*	95918167 - DN65/65

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
6	4.0	50	65	SL1.50.65.40.2.51D.C	98624259	98624259; 98626071; 98626075; 98626080; 98626299; 98626305; 98626310; 98626316; 98626478*; 98626485*; 98626489*; 98626551*; 98626694*; 98626701*; 98626705*; 98626757*	95918167 - DN65/65
4	2.2	50	80	SL1.50.80.22.2.50D.C	98617678	98617678; 98617679*; 98617680; 98617691*; 98626072; 98626082; 98626087; 98626300; 98626311; 98626317; 98626479*; 98626490*; 98626555*; 98626695*; 98626706*; 98626761*	96105765 - DN80/80
5	3.0	50	80	SL1.50.80.30.2.50D.C	98626076	98626073; 98626076; 98626083; 98626088; 98626301; 98626306; 98626312; 98626318; 98626480*; 98626484*; 98626491*; 98626556*; 98626696*; 98626700*; 98626707*; 98626762*	96105765 - DN80/80
6	4.0	50	80	SL1.50.80.40.2.51D.C	98624260	98624260; 98626074; 98626077; 98626084; 98626302; 98626307; 98626313; 98626319; 98626481*; 98626486*; 98626492*; 98626552*; 98626697*; 98626702*; 98626708*; 98626758*	96105765 - DN80/80
4	2.2	50	DN 65	SE1.50.65.22.2.50D.B	96047509	96047509; 96047511; 96047513; 96047515; 96048364; 96102066; 961177629; 961177673; 961177735; 96338698; 96338722	95918167 - DN65/65
5	3.0	50	DN 65	SE1.50.65.30.2.50D.B	96047517	96047517; 96047519; 96047521; 96047523; 96048368; 96102068; 961177630; 961177674; 961177736; 96338699; 96338723	95918167 - DN65/65
4	2.2	50	DN 80	SE1.50.80.22.2.50D.B	96047981	96047399; 96047981; 96047983; 96047985; 96047987; 96102073; 961177632; 961177676; 961177738; 96338701; 96338725	96105765 - DN80/80
7	0,9	65	65	SLV65.65.09.2.50B	96115123	96115123; 96115124*; 96115125; 96115126*; 96878475; 96878477*	95918167 - DN65/65
8	1,1	65	65	SLV65.65.11.2.50B	96106577	96106577; 96106578*; 96106579; 96106580*; 96566100; 96566101; 96566103*; 96878481*; 96882686	95918167 - DN65/65
9	1,5	65	65	SLV65.65.15.2.50B	96104192	96104192; 96104193*; 96104194; 96104195*; 96566104; 96566105; 96878503; 96878504*	95918167 - DN65/65
10	2.2	65	65	SLV65.65.22.2.50D.C	98624199	98624199; 98625855; 98626000; 98626044; 98626121; 98626169; 98626216; 98626267; 98626340*; 98626390*; 98626451*; 98626529*; 98626566*; 98626606*; 98626667*; 98626735*; 98626773; 98626803; 98626833; 98626863; 98626887; 98626917; 98626947; 98626977; 98627001*; 98627023*; 98627062*; 98627093*; 98627115*; 98627137*; 98627176*; 98627207*	95918167 - DN65/65

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
11	3.0	65	65	SIV65.65.30.2.50DC	98624165	98624165; 98625845; 98625990; 98626037; 98626111; 98626159; 98626206; 98626257; 98626320*; 98626388*; 98626441*; 98626506*; 98626527*; 98626604*; 98626657*; 98626763; 98626793; 98626823; 98626853; 98626877; 98626907; 98626937; 98626967; 98626991*; 98627021*; 98627052*; 98627091*; 98627105*; 98627135*; 98627166*; 98627205*	95918167 - DN65/65
12	4.0	65	65	SIV65.65.40.2.51DC	98624254	98624254; 98625847; 98625943; 98625992; 98626113; 98626161; 98626208; 98626259; 98626332*; 98626412*; 98626443*; 98626493*; 98626508*; 98626628*; 98626659*; 98626709*; 98626765; 98626795; 98626825; 98626855; 98626879; 98626909; 98626939; 98626969; 98626993*; 98627035*; 98627054*; 98627075*; 98627107*; 98627149*; 98627168*; 98627189*	95918167 - DN65/65
10	2.2	65	DN 65	SEV65.65.22.2.50D	96047697	96047697; 96047701; 96047705; 96047709; 96048462; 96102122; 96177653; 96177697; 96177759; 96338746; 96338766	95918167 - DN65/65
11	3.0	65	DN 65	SEV65.65.30.2.50D	96047713	96047713; 96047717; 96047721; 96047725; 96048470; 96102123; 96177654; 96177698; 96177760; 96338747; 96338767	95918167 - DN65/65
12	4.0	65	DN 65	SEV65.65.40.2.51D	96047729	96047729; 96047733; 96047737; 96047741; 96048478; 96102125; 96177655; 96177699; 96177761; 96338748; 96338768	95918167 - DN65/65



1 - 11 KW VORTEX PUMPS WITH 80 AND 100 MM FREE PASSAGE (STANDARD MOTOR VERSION)

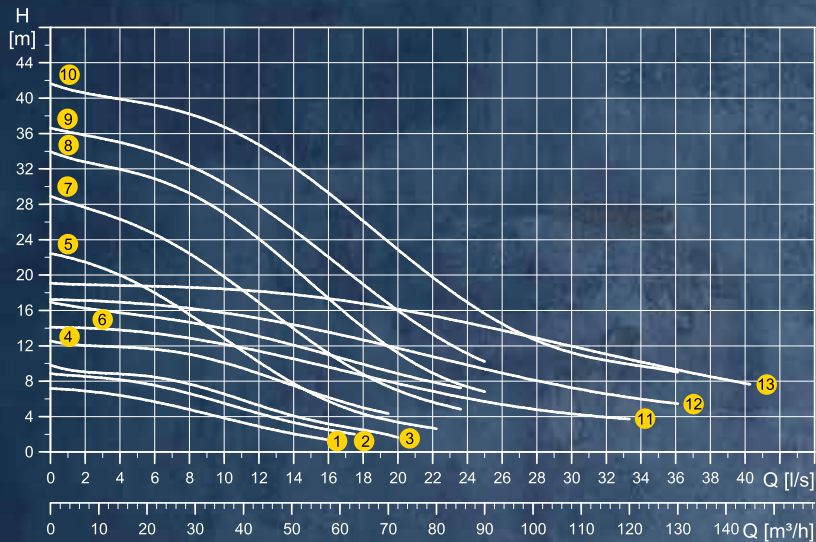


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	1.1	80	80	SLV.80.80.11.4.50D.C	98625975	98625871; 98625975; 98626016; 98626137; 98626185; 98626233; 98626366*; 98626395*; 98626534*; 98626582*; 98626611*; 98626740*; 98626783; 98626813; 98626843; 98626897; 98626927; 98626957; 98627011*; 98627026*; 98627096*; 98627125*; 98627140*; 98627210*	96105765 - DN80/80
2	1.3	80	80	SLV.80.80.13.4.50D.C	98624692	98624692; 98625873; 98626018; 98626139; 98626187; 98626236; 98626368*; 98626397*; 98626536*; 98626584*; 98626613*; 98626742*; 98626785; 98626815; 98626845; 98626899; 98626929; 98626959; 98627013*; 98627028*; 98627098*; 98627127*; 98627142*; 98627212*	96105765 - DN80/80
3	1.5	80	80	SLV.80.80.15.4.50D.C	98624694	98624694; 98625877; 98626022; 98626143; 98626191; 98626240; 98626372*; 98626401*; 98626540*; 98626588*; 98626617*; 98626746*; 98626787; 98626817; 98626847; 98626901; 98626931; 98626961; 98627015*; 98627030*; 98627100*; 98627129*; 98627144*; 98627214*	96105765 - DN80/80

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
4	2.2	80	80	SLV.80.80.22.4.50D.C	98624252	98624252; 98625891; 98626026; 98626059; 98626147; 98626194; 98626244; 98626285; 98626376*; 98626405*; 98626469*; 98626544*; 98626592*; 98626621*; 98626685*; 98626750*; 98626789; 98626819; 98626849; 98626873; 98626903; 98626933; 98626963; 98626987; 98627017*; 98627032*; 98627072*; 98627102*; 98627131*; 98627146*; 98627186*; 98627216*	96105765 - DN80/80
5	4.0	80	80	SLV.80.80.40.2.51D.C	98626039	98625849; 98625945; 98625994; 98626039; 98626767; 98626797; 98626827; 98626857	96105765 - DN80/80
6	4.0	80	80	SLV.80.80.40.4.51D.C	98624702	98624702; 98625868; 98625972; 98626013; 98626780; 98626810; 98626840; 98626870	96105765 - DN80/80
7	6.0	80	80	SLV.80.80.60.2.51D.C	98626041	98625851; 98625947; 98625996; 98626041; 98626117; 98626165; 98626212; 98626263; 98626336*; 98626416*; 98626447*; 98626497*; 98626562*; 98626632*; 98626663*; 98626713*; 98626769; 98626799; 98626829; 98626859; 98626883; 98626913; 98626943; 98626973; 98626997*; 98627039*; 98627058*; 98627079*; 98627111*; 98627153*; 98627172*; 98627193*	96105765 - DN80/80
8	7.5	80	80	SLV.80.80.75.2.51D.C	98624255	98624255; 98625857; 98625962; 98626002; 98626123; 98626171; 98626218; 98626269; 98626352*; 98626420*; 98626453*; 98626511*; 98626568*; 98626636*; 98626669*; 98626717*; 98626775; 98626805; 98626835; 98626865; 98626889; 98626919; 98626949; 98626979; 98627003*; 98627043*; 98627064*; 98627083*; 98627117*; 98627157*; 98627178*; 98627197*	96105765 - DN80/80
9	9.2	80	80	SLV.80.80.92.2.51D.C	98626047	98625859; 98625964; 98626004; 98626047; 98626125; 98626173; 98626220; 98626271; 98626354*; 98626422*; 98626455*; 98626513*; 98626570*; 98626638*; 98626671*; 98626719*; 98626777; 98626807; 98626837; 98626867; 98626891; 98626921; 98626951; 98626981; 98627005*; 98627045*; 98627066*; 98627085*; 98627119*; 98627159*; 98627180*; 98627199*	96105765 - DN80/80
10	11.0	80	80	SLV.80.80.110.2.51D.C	98624700	98624700; 98625853; 98625949; 98625998; 98626119; 98626167; 98626214; 98626265; 98626338*; 98626418*; 98626449*; 98626499*; 98626564*; 98626634*; 98626665*; 98626715*; 98626771; 98626801; 98626831; 98626861; 98626885; 98626915; 98626945; 98626975; 98626999*; 98627041*; 98627060*; 98627081*; 98627113*; 98627155*; 98627174*; 98627195*	96105765 - DN80/80
10	11.0	80	100	SLV.80.100.110.2.51D.C	98626043	98625854; 98625950; 98625999; 98626043; 98626120; 98626168; 98626215; 98626266; 98626339*; 98626419*; 98626450*; 98626500*; 98626565*; 98626635*; 98626666*; 98626716*; 98626772; 98626802; 98626832; 98626862; 98626886; 98626916; 98626946; 98626976; 98627000*; 98627042*; 98627061*; 98627082*; 98627114*; 98627156*; 98627175*; 98627196*	96105782 - DN100/100

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
11	4.0	100	100	SLV.100.100.40.4.51D.C	98626056	98625863; 98625870; 98625974; 98626015; 98626056; 98626136; 98626184; 98626232; 98626282; 98626365*; 98626430*; 98626466*; 98626521*; 98626581*; 98626646*; 98626682*; 98626727*; 98626782; 98626812; 98626842; 98626872; 98626896; 98626926; 98626956; 98626986; 98627010*; 98627049*; 98627071*; 98627089*; 98627124*; 98627163*; 98627185*; 98627203*	96105782 - DN100/100
12	5.5	100	100	SLV.100.100.55.4.51D.C	98626031	98625897; 98625984; 98626031; 98626065; 98626153; 98626200; 98626251; 98626291; 98626382*; 98626411*; 98626435*; 98626550*; 98626598*; 98626627*; 98626651*; 98626756*; 98626791; 98626821; 98626851; 98626875; 98626905; 98626935; 98626965; 98626989; 98627019*; 98627034*; 98627050*; 98627104*; 98627133*; 98627148*; 98627164*; 98627218*	96105782 - DN100/100
13	7.5	100	100	SLV.100.100.75.4.51D.C	98624704	98624704; 98625902; 98625989; 98626036; 98626158; 98626205; 98626256; 98626296; 98626387*; 98626440*; 98626475*; 98626526*; 98626603*; 98626656*; 98626691*; 98626732*; 98626792; 98626822; 98626852; 98626876; 98626906; 98626936; 98626966; 98626990; 98627020*; 98627051*; 98627074*; 98627090*; 98627134*; 98627165*; 98627188*; 98627204*	96105782 - DN100/100
1	1.1	80	DN 80	SEV.80.80.11.4.50D	96047745	96047745; 96047748; 96047751; 96047754; 96048486; 96102132; 96177659; 96177703; 96177765; 96338752; 96338772; 96889323; 96962192; 96962883; 96966646; 97637756; 97638036; 97638154; 97638245; 97679037; 97679100; 97679507; 97683044	96105765 - DN80/80
2	1.3	80	DN 80	SEV.80.80.13.4.50D	96047757	96047757; 96047760; 96047763; 96047766; 96048492; 96102133; 96177660; 96177704; 96177766; 96338753; 96338773; 96889324; 96962193; 96962885; 96966648; 97637757; 97638037; 97638155; 97638246; 97679038; 97679101; 97679508; 97683045	96105765 - DN80/80
3	1.5	80	DN 80	SEV.80.80.15.4.50D	96047769	96047769; 96047772; 96047775; 96047778; 96048498; 96102134; 96177661; 96177705; 96177767; 96338754; 96338774; 96889325; 96962194; 96962886; 96966649; 97637758; 97638038; 97638156; 97638247; 97679039; 97679102; 97679509; 97683046	96105765 - DN80/80
4	2.2	80	DN 80	SEV.80.80.22.4.50D	96047781	96047497; 96047781; 96047785; 96047789; 96047793; 96102135; 96177662; 96177706; 96177768; 96338755; 96889326; 96962195; 96962887; 96966650; 97637759; 97638039; 97638157; 97638248; 97679040; 97679103; 97679510; 97683047	96105765 - DN80/80

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
5	4.0	80	DN 80	SEV.80.80.40.2.51D	96047829	96047473; 96047829; 96047833; 96047837; 96047841; 96102138; 96177664; 96177708; 96177770; 96338757; 96338777; 96889328; 96962197; 96962888; 96966651; 97637760; 97638051; 97638159; 97638250; 97679042; 97679105; 97679512; 97683049	96105765 - DN80/80
6	4.0	80	DN 80	SEV.80.80.40.4.51D	96047797	96047489; 96047797; 96047801; 96047813; 96047817; 96102136; 96177663; 96177707; 96177769; 96338756; 96338776; 96889327; 96962196; 96962889; 96966652; 97637761; 97638040; 97638158; 97638249; 97679041; 97679104; 97679511; 97683048	96105765 - DN80/80
7	6.0	80	DN 80	SEV.80.80.60.2.51D	96047845	96047465; 96047845; 96047849; 96047853; 96047857; 96102141; 96177665; 96177709; 96177771; 96338758; 96338778; 96889329; 96962198; 96962890; 96966653; 97637762; 97638052; 97638160; 97638251; 97679043; 97679106; 97679513; 97683050	96105765 - DN80/80
8	7.5	80	DN 80	SEV.80.80.75.2.51D	96047861	96047457; 96047861; 96047865; 96047869; 96047873; 96102144; 96177666; 96177710; 96177772; 96338759; 96338779; 96889330; 96962199; 96966654; 96980890; 97637763; 97638053; 97638161; 97638252; 97679044; 97679107; 97679514; 97683051	96105765 - DN80/80
9	9.2	80	DN 80	SEV.80.80.92.2.51D	96047207	96047192; 96047195; 96047201; 96047204; 96047207; 96102147; 96177667; 96177711; 96177773; 96338760; 96338780; 96889331; 96962200; 96962891; 96966655; 97637764; 97638054; 97638162; 97638253; 97679045; 97679108; 97679515; 97683052	96105765 - DN80/80
10	11.0	80	DN 80	SEV.80.80.110.2.51D	96047877	96047449; 96047877; 96047881; 96047885; 96047889; 96102150; 96177668; 96177712; 96177774; 96338761; 96338781; 96889332; 96962201; 96962892; 96966656; 97637765; 97638055; 97638163; 97638254; 97679046; 97679109; 97679516; 97683053	96105765 - DN80/80
11	4.0	100	DN 100	SEV.100.100.40.4.51D	96047925	96047427; 96047925; 96047929; 96047933; 96047937; 96102154; 96177670; 96177714; 96177776; 96338763; 96338783; 96889344; 96962224; 96965900; 96966669; 97637777; 97638067; 97638175; 97638266; 97679058; 97679121; 97679528; 97683065	96105782 - DN100/100
12	5.5	100	DN 100	SEV.100.100.55.4.51D	96047941	96047419; 96047941; 96047945; 96047949; 96047953; 96102157; 96177671; 96177715; 96177777; 96338764; 96338784; 96889345; 96962225; 96965901; 96966670; 97637778; 97638068; 97638176; 97638267; 97679059; 97679122; 97679529; 97683066	96105782 - DN100/100
13	7.5	100	DN 100	SEV.100.100.75.4.51D	96047957	96047411; 96047957; 96047961; 96047965; 96047969; 96102160; 96177672; 96177716; 96177778; 96338765; 96338785; 96889346; 96962226; 96965932; 96966671; 97637779; 97638069; 97638177; 97638268; 97679060; 97679123; 97679530; 97683067	96105782 - DN100/100

1 - 11 KW S-TUBE PUMPS WITH 80 AND 100 MM FREE PASSAGE (STANDARD MOTOR VERSION)

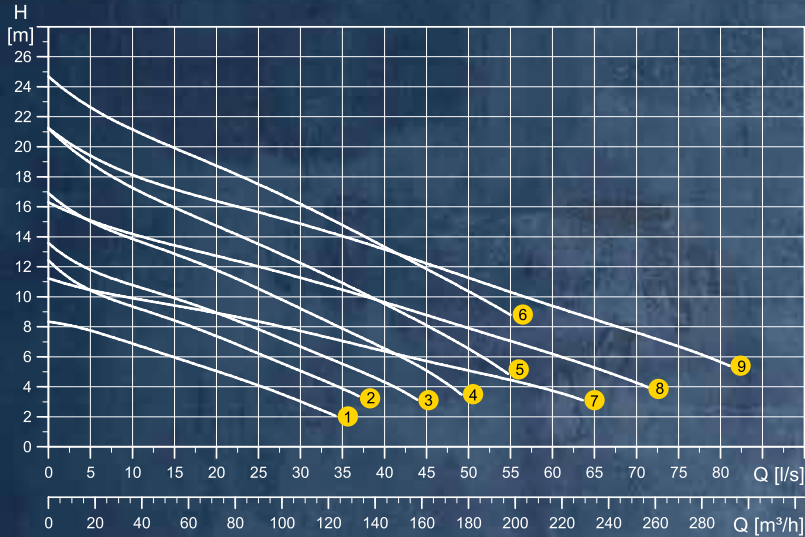


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	1.5	80	80	SL1.80.80.15.4.50DC	98624693	98624693; 98625875; 98626020; 98626141; 98626189; 98626238; 98626370; 98626399; 98626538; 98626586; 98626615; 98626744*	96105765 - DN80/80
2	2.2	80	80	SL1.80.80.22.4.50DC	98624251	98624251; 98624696; 98625879; 98626024; 98626057; 98626145; 98626242; 98626283; 98626374; 98626403; 98626467; 98626542; 98626590; 98626619; 98626683; 98626748*	96105765 - DN80/80
3	3.0	80	80	SL1.80.80.30.4.50DC	98624669	98624669; 98625861; 98626006; 98626049; 98626127; 98626175; 98626222; 98626273; 98626356; 98626392; 98626457; 98626531; 98626572; 98626608; 98626673; 98626737*	96105765 - DN80/80
4	4.0	80	80	SL1.80.80.40.4.51DC	98626052	98625864; 98625968; 98626009; 98626052; 98626130; 98626178; 98626225; 98626276; 98626359; 98626424; 98626460; 98626515; 98626575; 98626640; 98626676; 98626721*	96105765 - DN80/80

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
5	5.5	80	80	SL1.80.80.55.4.51DC	98624697	98624697; 98625893; 98625980; 98626061; 98626149; 98626196; 98626246; 98626287; 98626378; 98626407; 98626431; 98626546; 98626594; 98626623; 98626647; 98626752*	96105765 - DN80/80
6	7.5	80	80	SL1.80.80.75.4.51DC	98624703	98624703; 98625898; 98625985; 98626032; 98626154; 98626201; 98626252; 98626292; 98626383; 98626436; 98626471; 98626522; 98626599; 98626652; 98626687; 98626728*	96105765 - DN80/80
1	1.5	80	100	SL1.80.100.15.4.50DC	98625977	98625876; 98625977; 98626021; 98626142; 98626190; 98626239; 98626371; 98626400; 98626539; 98626587; 98626616; 98626745*	96105782 - DN100/100
2	2.2	80	100	SL1.80.100.22.4.50DC	98624695	98624695; 98625880; 98626025; 98626058; 98626146; 98626193; 98626243; 98626284; 98626375; 98626404; 98626468; 98626543; 98626591; 98626620; 98626684; 98626749*	96105782 - DN100/100
3	3.0	80	100	SL1.80.100.30.4.50DC	98625966	98625862; 98625966; 98626007; 98626050; 98626128; 98626176; 98626223; 98626274; 98626357; 98626393; 98626458; 98626532; 98626573; 98626609; 98626674; 98626738*	96105782 - DN100/100
4	4.0	80	100	SL1.80.100.40.4.51DC	98626053	98625865; 98625969; 98626010; 98626053; 98626131; 98626179; 98626226; 98626277; 98626360; 98626425; 98626461; 98626516; 98626576; 98626641; 98626677; 98626722*	96105782 - DN100/100
5	5.5	80	100	SL1.80.100.55.4.51DC	98626028	98625894; 98625981; 98626028; 98626062; 98626150; 98626197; 98626247; 98626288; 98626379; 98626408; 98626432; 98626547; 98626595; 98626624; 98626648; 98626753*	96105782 - DN100/100
6	7.5	80	100	SL1.80.100.75.4.51DC	98626066	98625899; 98625986; 98626033; 98626066; 98626155; 98626202; 98626253; 98626293; 98626384; 98626437; 98626472; 98626523; 98626600; 98626653; 98626688; 98626729*	96105782 - DN100/100
7	4.0	100	100	SL1.100.100.40.4.51DC	98624701	98624701; 98625866; 98625970; 98626011; 98626132; 98626180; 98626227; 98626278; 98626361; 98626426; 98626462; 98626517; 98626577; 98626642; 98626678; 98626723*	96105782 - DN100/100
8	5.5	100	100	SL1.100.100.55.4.51DC	98626029	98625895; 98625982; 98626029; 98626063; 98626151; 98626198; 98626248; 98626289; 98626380; 98626409; 98626433; 98626548; 98626596; 98626625; 98626649; 98626754*	96105782 - DN100/100

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
9	7.5	100	100	SL1.100.100.75.4.51D.C	98626067	98625900; 98625987; 98626034; 98626067; 98626156; 98626203; 98626254; 98626294; 98626385*; 98626438*; 98626473*; 98626524*; 98626601*; 98626654*; 98626689*; 98626730*	96105782 - DN100/100
8	5.5	100	150	SL1.100.150.55.4.51D.C	98626030	98625896; 98625983; 98626030; 98626064; 98626152; 98626199; 98626250; 98626290; 98626381*; 98626410*; 98626434*; 98626549*; 98626597*; 98626626*; 98626650*; 98626755*	98617437 - DN150/150
9	7.5	100	150	SL1.100.150.75.4.51D.C	98626068	98625901; 98625988; 98626035; 98626068; 98626157; 98626204; 98626255; 98626295; 98626386*; 98626439*; 98626474*; 98626525*; 98626602*; 98626655*; 98626690*; 98626731*	98617437 - DN150/150
1	1.5	80	DN 80	SE1.80.80.15.4.50D.B	96047533	96047533; 96047537; 96047541; 96047545; 96048376; 96102080; 96177635; 96177679; 96177741; 96338704; 96338728	96105765 - DN80/80
2	2.2	80	DN 80	SE1.80.80.22.4.50D.B	96047549	96047549; 96047553; 96047557; 96047561; 96048384; 96102081; 96177636; 96177680; 96338705; 96338729	96105765 - DN80/80
6	7.5	80	DN 80	SE1.80.80.75.4.51D.B	96047627	96047627; 96047631; 96047635; 96047638; 96048424; 96102090; 96177640; 96177684; 96177746; 96338709; 96338733	96105765 - DN80/80
1	1.5	80	DN 100	SE1.80.100.15.4.50D.B	96048005	96047387; 96048005; 96048009; 96048013; 96048017; 96102092; 96177641; 96177685; 96177747; 96338710; 96338734; 96618066	96105782 - DN100/100
2	2.2	80	DN 100	SE1.80.100.22.4.50D.B	96048021	96047379; 96048021; 96048025; 96048029; 96048033; 96102093; 96177642; 96177686; 96177748; 96338711; 96338735; 96618067	96105782 - DN100/100
4	4.0	80	DN 100	SE1.80.100.40.4.51D.B	96048069	96047355; 96048069; 96048073; 96048077; 96048081; 96102096; 96177644; 96177688; 96177750; 96338713; 96338737; 96618069	96105782 - DN100/100
5	5.5	80	DN 100	SE1.80.100.55.4.51D.B	96048085	96047347; 96048085; 96048089; 96048093; 96048096; 96102099; 96177645; 96177689; 96177751; 96338714; 96338738; 96618090	96105782 - DN100/100
9	7.5	100	DN 100	SE1.100.100.75.4.51D.B	96047671	96047671; 96047675; 96047679; 96047682; 96048448; 96102111; 96177649; 96177693; 96177755; 96338742	96105782 - DN100/100
9	7.5	100	DN 150	SE1.100.150.75.4.51D.B	96048143	96047315; 96048143; 96048147; 96048151; 96048154; 96102120; 96177652; 96177696; 96177758; 96338745	98617437 - DN150/150



9 - 30 KW VORTEX PUMPS WITH 80 MM FREE PASSAGE (STANDARD MOTOR VERSION)

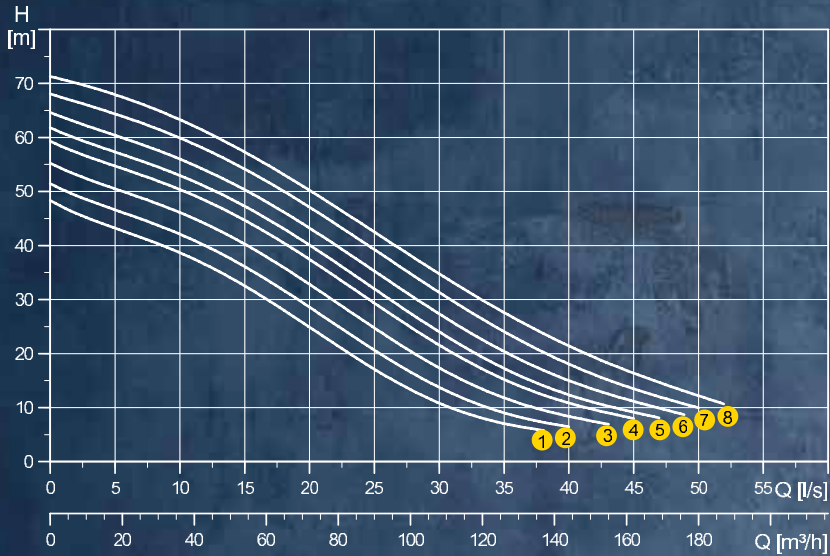


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	13	80	DN 80	SLV.80.80.130.2.52H.S.N.51D	98179853	98179853; 98179922*; 98179990	96105765 - DN80/80
2	15	80	DN 80	SLV.80.80.150.2.52H.S.N.51D	98174829	98174829; 98174902*; 98174970	96105765 - DN80/80
3	17	80	DN 80	SLV.80.80.170.2.52H.S.N.51D	98179850	98179850; 98179919*; 98179987	96105765 - DN80/80
4	18,5	80	DN 80	SLV.80.80.185.2.52H.S.N.51D	98057789	98057789; 98174899*; 98174967	96105765 - DN80/80
5	20	80	DN 80	SLV.80.80.200.2.52H.S.N.51D	98179847	98179847; 98179916*; 98179984	96105765 - DN80/80
6	22	80	DN 80	SLV.80.80.220.2.52H.S.N.51D	98057788	98057788; 98174896*; 98174964	96105765 - DN80/80
7	24	80	DN 80	SLV.80.80.240.2.52H.S.N.51D	98179844	98179844; 98179913*; 98179981	96105765 - DN80/80
8	26,5	80	DN 80	SLV.80.80.265.2.52H.S.N.51D	98057787	98057787; 98174893*; 98174961	96105765 - DN80/80
1	13	80	DN 80	SEV.80.80.130.2.52H.C.N.51D	98179854	98179854; 98179855; 98179923*; 98179924*; 98179991; 98179992	96105765 - DN80/80
2	15	80	DN 80	SEV.80.80.150.2.52H.C.N.51D	98174830	98174830; 98174831; 98174903*; 98174904*; 98174971; 98174972	96105765 - DN80/80
3	17	80	DN 80	SEV.80.80.170.2.52H.C.N.51D	98179851	98179851; 98179852; 98179920*; 98179921*; 98179988; 98179989	96105765 - DN80/80
4	18,5	80	DN 80	SEV.80.80.185.2.52H.C.N.51D	98174827	98174827; 98174828; 98174900*; 98174901*; 98174968; 98174969	96105765 - DN80/80
5	20	80	DN 80	SEV.80.80.200.2.52H.C.N.51D	98179848	98179848; 98179849; 98179917*; 98179918*; 98179985; 98179986	96105765 - DN80/80

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
6	22	80	DN 80	SEV.80.80.220.2.52H.C.N.51D	98174825	98174825; 98174826; 98174897*; 98174898*; 98174965; 98174966	96105765 - DN80/80
7	24	80	DN 80	SEV.80.80.240.2.52H.C.N.51D	98179845	98179845; 98179846; 98179914*; 98179915*; 98179982; 98179983	96105765 - DN80/80
8	26,5	80	DN 80	SEV.80.80.265.2.52H.C.N.51D	98145083	98145083; 98145085; 98174894*; 98174895*; 98174962; 98174963	96105765 - DN80/80




9 - 30 KW S-TUBE PUMPS WITH HIGH PRESSURE HYDRAULICS (S AND H HYDRAULICS IN STANDARD MOTOR VERSION)

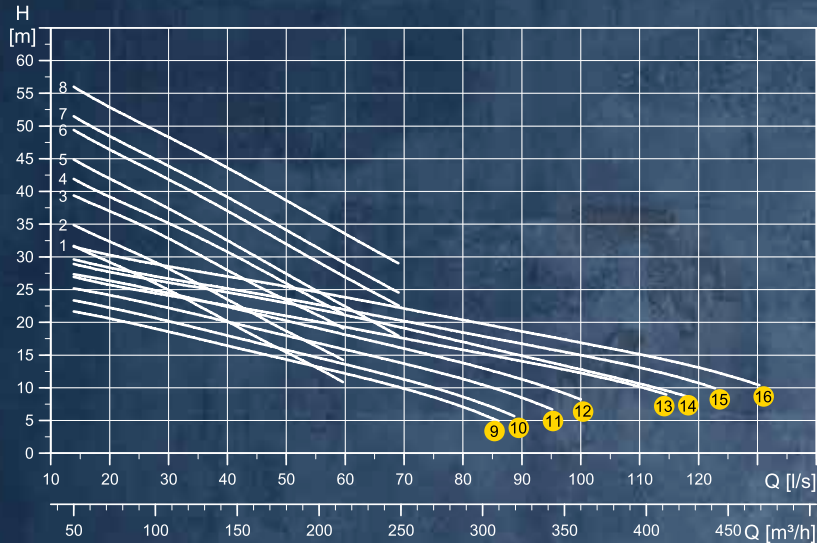

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	13	75	DN 100	SL1.75.100.130.2.52S.S.N.51D	98179797	98179797; 98179866*; 98179934	96105782 - DN100/100
2	15	75	DN 100	SL1.75.100.150.2.52S.S.N.51D	98174790	98174790; 98174846*; 98174914	96105782 - DN100/100
3	17	75	DN 100	SL1.75.100.170.2.52S.S.N.51D	98179794	98179794; 98179863*; 98179931	96105782 - DN100/100
4	18,5	75	DN 100	SL1.75.100.185.2.52S.S.N.51D	98174787	98174787; 98174843*; 98174911	96105782 - DN100/100
5	20	80	DN 100	SL1.80.100.200.2.52S.C.N.51D	98179791	98179791; 98179860*; 98179928	96105782 - DN100/100
6	22	80	DN 100	SL1.80.100.220.2.52S.C.N.51D	98174784	98174784; 98174800*; 98174908	96105782 - DN100/100
7	24	80	DN 100	SL1.80.100.240.2.52S.C.N.51D	98179778	98179778; 98179857*; 98179925	96105782 - DN100/100
8	26,5	80	DN 100	SL1.80.100.265.2.52S.C.N.51D	98145049	98145049; 98174797*; 98174905	96105782 - DN100/100
1	13	75	DN 100	SE1.75.100.130.2.52S.H.N.51D	98179799	98179798; 98179799; 98179867*; 98179868*; 98179935; 98179936	For horizontal Installation
2	15	75	DN 100	SE1.75.100.150.2.52S.H.N.51D	98174802	98174801; 98174802; 98174847*; 98174848*; 98174915; 98174916	For horizontal Installation
3	17	75	DN 100	SE1.75.100.170.2.52S.H.N.51D	98179796	98179795; 98179796; 98179864*; 98179865*; 98179932; 98179933	For horizontal Installation
9	10	85	DN 150	SE1.85.150.100.4.52H.H.N.51D	98179811	98179810; 98179811; 98179879*; 98179880*; 98179947; 98179948	For horizontal Installation
2	15	75	DN 100	SE1.75.100.150.2.52S.C.N.51D	98174801	98174801; 98174802; 98174847*; 98174848*; 98174915; 98174916	96105782 - DN150/150
3	17	75	DN 100	SE1.75.100.170.2.52S.C.N.51D	98179795	98179795; 98179796; 98179864*; 98179865*; 98179932; 98179933	96105782 - DN150/150
4	18,5	75	DN 100	SE1.75.100.185.2.52S.C.N.51D	98174788	98174788; 98174789; 98174844*; 98174845*; 98174912; 98174913	96105782 - DN150/150

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
5	20	80	DN 100	SE1.80.100.200.2.52S.C.N.51D	98179792	98179792; 98179793; 98179861*; 98179862*; 98179929; 98179930	96105782 - DN100/100
6	22	80	DN 100	SE1.80.100.220.2.52S.C.N.51D	98174785	98174785; 98174786; 98174841*; 98174842*; 98174909; 98174910	96105782 - DN100/100
7	24	80	DN 100	SE1.80.100.240.2.52S.C.N.51D	98179779	98179779; 98179780; 98179858*; 98179859*; 98179926; 98179927	96105782 - DN100/100
8	26,5	80	DN 100	SE1.80.100.265.2.52S.C.N.51D	98145062	98145062; 98145063; 98174798*; 98174799*; 98174906; 98174907	96105782 - DN100/100
9	10	85	DN 150	SL1.85.150.100.4.52H.S.N.51D	98179809	98179809; 98179878*; 98179946	98617437 - DN150/150
10	11	85	DN 150	SL1.85.150.110.4.52H.S.N.51D	98057803	98057803; 98174858*; 98174926	98617437 - DN150/150
11	13	85	DN 150	SL1.85.150.130.4.52H.S.N.51D	98179806	98179806; 98179875*; 98179943	98617437 - DN150/150
12	15	85	DN 150	SL1.85.150.150.4.52H.S.N.51D	98057802	98057802; 98174855*; 98174923	98617437 - DN150/150
13	17	95	DN 150	SL1.95.150.170.4.52H.S.N.51D	98179803	98179803; 98179872*; 98179940	98617437 - DN150/150
14	18,5	95	DN 150	SL1.95.150.185.4.52H.S.N.51D	98057801	98057801; 98174852*; 98174920	98617437 - DN150/150
15	20	95	DN 150	SL1.95.150.200.4.52H.S.N.51D	98179800	98179800; 98179869*; 98179937	98617437 - DN150/150
16	22	95	DN 150	SL1.95.150.220.4.52H.S.N.51D	98057790	98057790; 98174849*; 98174917	98617437 - DN150/150
9	10	85	DN 150	SE1.85.150.100.4.52H.C.N.51D	98179810	98179810; 98179811; 98179879*; 98179880*; 98179947; 98179948	98617437 - DN150/150
10	11	85	DN 150	SE1.85.150.110.4.52H.C.N.51D	98174807	98174807; 98174808; 98174859*; 98174860*; 98174927; 98174928	98617437 - DN150/150
11	13	85	DN 150	SE1.85.150.130.4.52H.C.N.51D	98179807	98179807; 98179808; 98179876*; 98179877*; 98179944; 98179945	98617437 - DN150/150
12	15	85	DN 150	SE1.85.150.150.4.52H.C.N.51D	98174805	98174805; 98174806; 98174856*; 98174857*; 98174924; 98174925	98617437 - DN150/150
13	17	95	DN 150	SE1.95.150.170.4.52H.C.N.51D	98179804	98179804; 98179805; 98179873*; 98179874*; 98179941; 98179942	98617437 - DN150/150
14	18,5	95	DN 150	SE1.95.150.185.4.52H.C.N.51D	98174803	98174803; 98174804; 98174853*; 98174854*; 98174921; 98174922	98617437 - DN150/150
15	20	95	DN 150	SE1.95.150.200.4.52H.C.N.51D	98179801	98179801; 98179802; 98179870*; 98179871*; 98179938; 98179939	98617437 - DN150/150
16	22	95	DN 150	SE1.95.150.220.4.52H.C.N.51D	98144980	98144980; 98145014; 98174850*; 98174851*; 98174918; 98174919	98617437 - DN150/150

9 - 30 KW S-TUBE PUMPS WITH HIGH FLOW HYDRAULICS (M AND E HYDRAULICS IN STANDARD MOTOR VERSION)

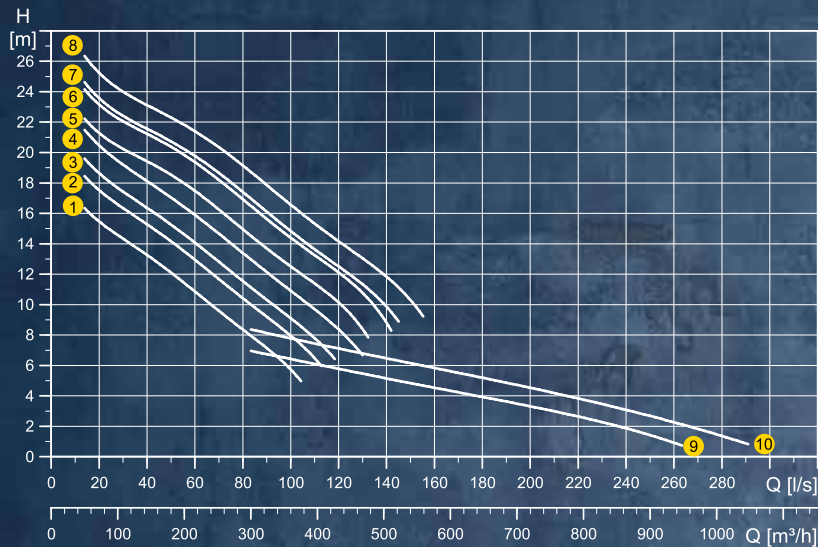


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	10	110	DN 200	SE1.110.200.100.4.52M.S.N.51D	98179821	98179821; 98179890*; 98179958	98365764 - DN200/ DN200
2	11	110	DN 200	SE1.110.200.110.4.52M.S.N.51D	98057806	98057806; 98174870*; 98174938	98365764 - DN200/ DN200
3	13	110	DN 200	SE1.110.200.130.4.52M.S.N.51D	98179818	98179818; 98179887*; 98179955	98365764 - DN200/ DN200
4	15	110	DN 200	SE1.110.200.150.4.52M.S.N.51D	98174811	98174811; 98174867*; 98174935	98365764 - DN200/ DN200
5	17	110	DN 200	SE1.110.200.170.4.52M.S.N.51D	98179815	98179815; 98179884*; 98179952	98365764 - DN200/ DN200
6	18,5	110	DN 200	SE1.110.200.185.4.52M.S.N.51D	98057805	98057805; 98174864*; 98174932	98365764 - DN200/ DN200
7	20	110	DN 200	SE1.110.200.200.4.52M.S.N.51D	98179812	98179812; 98179881*; 98179949	98365764 - DN200/ DN200
8	22	110	DN 200	SE1.110.200.220.4.52M.S.N.51D	98057804	98057804; 98174861*; 98174929	98365764 - DN200/ DN200
1	10	110	DN 200	SE1.110.200.100.4.52M.C.N.51D	98179822	98179822; 98179823; 98179891*; 98179892*; 98179959; 98179960	98365764 - DN200/ DN200
2	11	110	DN 200	SE1.110.200.110.4.52M.C.N.51D	98174814	98174814; 98174815; 98174871*; 98174872*; 98174939; 98174940	98365764 - DN200/ DN200
3	13	110	DN 200	SE1.110.200.130.4.52M.C.N.51D	98179819	98179819; 98179820; 98179888*; 98179889*; 98179956; 98179957	98365764 - DN200/ DN200

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
4	15	110	DN 200	SE1.110.200.150.4.52M.C.N.51D	98174812	98174812; 98174813; 98174868*; 98174869*; 98174936; 98174937	98365764 - DN200/ DN200
5	17	110	DN 200	SE1.110.200.170.4.52M.C.N.51D	98179816	98179816; 98179817; 98179885*; 98179886*; 98179953; 98179954	98365764 - DN200/ DN200
6	18,5	110	DN 200	SE1.110.200.185.4.52M.C.N.51D	98174809	98174809; 98174810; 98174865*; 98174866*; 98174933; 98174934	98365764 - DN200/ DN200
7	20	110	DN 200	SE1.110.200.200.4.52M.C.N.51D	98179813	98179813; 98179814; 98179882*; 98179883*; 98179950; 98179951	98365764 - DN200/ DN200
8	22	110	DN 200	SE1.110.200.220.4.52M.C.N.51D	98145015	98145015; 98145022; 98174862*; 98174863*; 98174930; 98174931	98365764 - DN200/ DN200
9	11	160	DN 300	SE1.160.300.110.6.52E.S.N.51D	98179840	98179840; 98179909*; 98179977	98381199 - DN300/ DN300
10	13	160	DN 300	SE1.160.300.130.6.52E.S.N.51D	98057810	98057810; 98174889*; 98174957	98381199 - DN300/ DN300
9	11	160	300	SE1.160.300.110.6.52E.S.N	98179840	98179841; 98179909*; 98179910*; 98179977; 98179978	300/ DN300 (Part no. 97908892)
10	13	160	300	SE1.160.300.130.6.52E.S.N	98057810	98145102; 98174889*; 98174890*; 98174957; 98174958	300/ DN300 (Part no. 97908892)




EF 0.6 - 0.9 KW EFFLUENT PUMPS WITH 30 MM FREE PASSAGE WITH EXPLOSION PROOF MOTOR

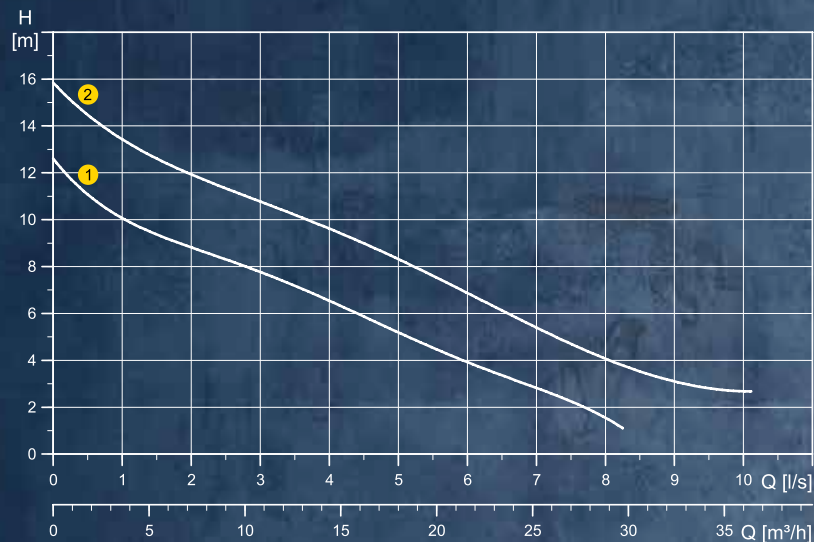

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	0,6	30	R 2	EF30.50.06.Ex.2.50B	96106551	96106550; 96106551*; 96106552; 96106553*; 96566084; 96566086; 96566087*; 96877510; 96877514	
2	0,9	30	R 2	EF30.50.09.Ex.2.50B	96115116	96115115; 96115116*; 96115117; 96115118*; 96566088; 96566090*; 96877516; 96877532	

SEG 0.9 - 4.0 KW GRINDER PUMPS WITH EXPLOSION PROOF MOTOR

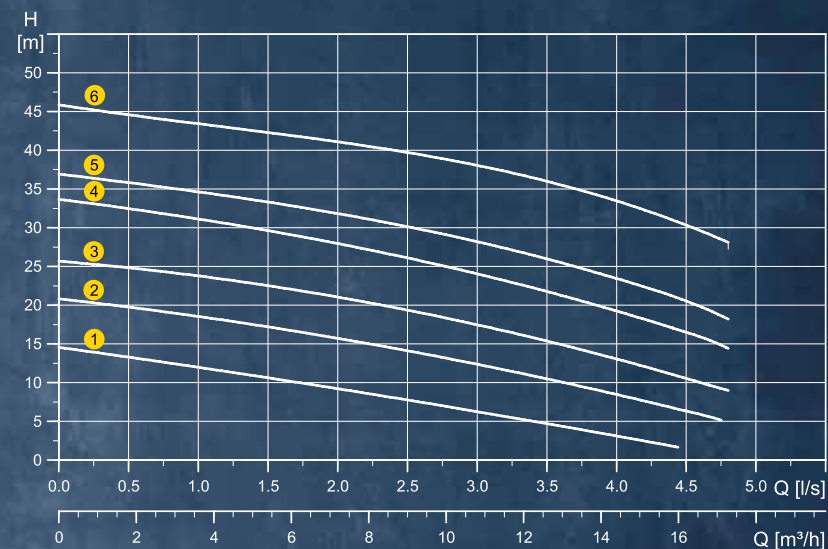


Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	0,9		DN 40	SEG.40.09.EX.2.1.50Z	96075894	96075893; 96075894; 96076161; 96076212; 96076213; 96076228; 96878505; 96878507	98247423 - DN40
1	0,9		DN 40	SEG.40.09.EX.2.50B	96075898	96075897; 96075898; 96075919; 96076162; 96076214; 96076215; 96076229; 96878506; 96878508	98247423 - DN40
2	1,2		DN 40	SEG.40.12.EX.2.1.50Z	96075902	96075901; 96075902; 96076163; 96076216; 96076217; 96076230; 96878509; 96878512	98247423 - DN40
2	1,2		DN 40	SEG.40.12.EX.2.50B	96075906	96075905; 96075906; 96075920; 96076164; 96076218; 96076219; 96076231; 96878510; 96878513	98247423 - DN40
3	1,5		DN 40	SEG.40.15.EX.2.1.50Z	98280725	98280724; 98280725; 98280726; 98280948	98247423 - DN40
3	1,5		DN 40	SEG.40.15.EX.2.50B	96075910	96075909; 96075910; 96075921; 96076165; 96076220; 96076221; 96076232; 96878514; 96878515	98247423 - DN40
4	2,6		DN 40	SEG.40.26.EX.2.50B	96075914	96075913; 96075914; 96075922; 96076166; 96076222; 96076223; 96076233; 96878516; 96878517	98247423 - DN40
5	3,1		DN 40	SEG.40.31.EX.2.50B	96075916	96075915; 96075916; 96075923; 96076167; 96076224; 96076225; 96076234; 96878518; 96878519	98247423 - DN40
6	4,0		DN 40	SEG.40.40.EX.2.50B	96075918	96075917; 96075918; 96075924; 96076168; 96076226; 96076227; 96076235; 96878520; 96878521	98247423 - DN40

SL 1-11KW VORTEX AND S-TUBE PUMPS

WITH 50 TO 80 MM FREE PASSAGE

WITH EXPLOSION PROOF MOTOR

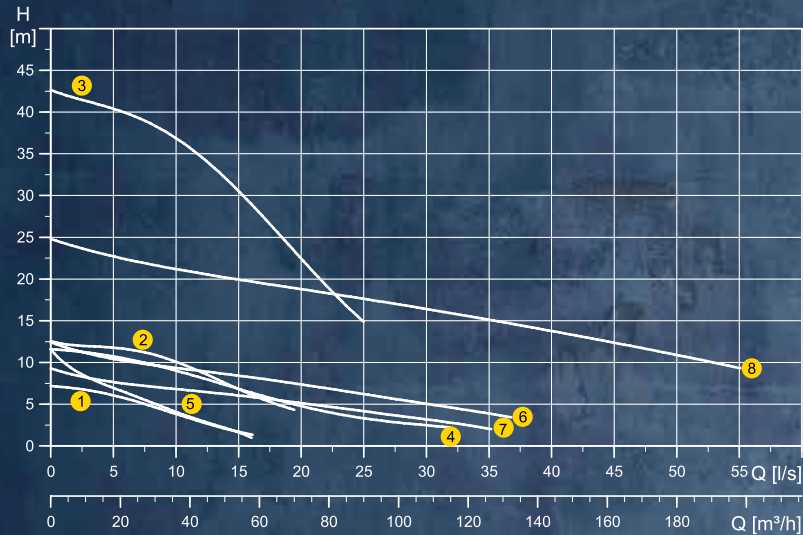

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
1	1.1	80	80	SLV.80.80.11.EX.4.50D.C	98626611	98625871; 98625975; 98626016; 98626137; 98626185; 98626233; 98626366; 98626395; 98626534; 98626582; 98626611; 98626740; 98626783; 98626813; 98626843; 98626897; 98626927; 98626957; 98627011; 98627026; 98627096; 98627125; 98627140; 98627210*	96105765 - DN80/80
2	2.2	80	80	SLV.80.80.22.EX.4.50D.C	98626621	98624252; 98625891; 98626026; 98626059; 98626147; 98626194; 98626244; 98626285; 98626376; 98626405; 98626469; 98626544; 98626592; 98626621; 98626685; 98626750; 98626789; 98626819; 98626849; 98626873; 98626903; 98626933; 98626963; 98626987; 98627017; 98627032; 98627072; 98627102; 98627131; 98627146; 98627186; 98627216*	96105765 - DN80/80

Curve no.	Motor size (kW)	Free passage (mm)	"Discharge (DN)"	Product Type key	Product number (in stock)	Related product numbers	Flygt adaptor information
3	11.0	80	80	SLV.80.80.110.EX.2.51D.C	98626665	98624700; 98625853; 98625949; 98625998; 98626119; 98626167; 98626214; 98626265; 98626338; 98626418; 98626449; 98626499; 98626564; 98626634; 98626665; 98626715; 98626771; 98626801; 98626831; 98626861; 98626885; 98626915; 98626945; 98626975; 98626999; 98627041; 98627060; 98627081; 98627113; 98627155; 98627174; 98627195*	96105765 - DN80/80
4	3.0	100	100	SLV.100.100.30.EX.4.50D.C	98626610	98625967; 98626008; 98626051; 98626129; 98626177; 98626224; 98626275; 98626358; 98626394; 98626459; 98626533; 98626574; 98626610; 98626675; 98626739; 98626779; 98626809; 98626839; 98626869; 98626893; 98626923; 98626953; 98626983; 98627007; 98627025; 98627068; 98627095; 98627121; 98627139; 98627182; 98627209*	96105782 - DN100/100
5	0.9	50	65	SL.150.65.09.Ex.2.50B	96106568	96106566; 96106567; 96106568; 96106569; 96106570; 96106571; 96106572; 96878451; 96878453*	95918167 - DN65/65
6	2.2	80	80	SL.180.80.22.EX.4.50D.C	98626619	98624251; 98624696; 98625879; 98626024; 98626057; 98626145; 98626242; 98626283; 98626374; 98626403; 98626467; 98626542; 98626590; 98626619; 98626683; 98626748*	96105765 - DN80/80
7	1.5	80	100	SL.180.100.15.EX.4.50D.C	98626616	98625876; 98625977; 98626021; 98626142; 98626190; 98626239; 98626371; 98626400; 98626539; 98626587; 98626616; 98626745*	96105782 - DN100/100
8	7.5	80	100	SL.180.100.75.EX.4.51D.C	98626688	98625899; 98625986; 98626033; 98626066; 98626155; 98626202; 98626253; 98626293; 98626384; 98626437; 98626472; 98626523; 98626600; 98626653; 98626688; 98626729*	96105782 - DN100/100



Although we have done our utmost to ensure the accuracy of this guide, Grundfos cannot be held accountable for potential errors or typos and will not cover any costs caused by faulty or misleading information.

1216/Water Utility/11937 BrandBox